



# NVENT CADDY SPEED LINK LD LOCKING DEVICE



## CARACTERÍSTICAS

Low-profile locking device minimizes visual impact

Suitable for 1.5 mm nVent CADDY Speed Link cable

## SPECIFICATIONS


Table 1/1

| Número do catálogo | Número do artigo | Material                        | Wire Rope Diameter | Altura (H) | Largura (W) |
|--------------------|------------------|---------------------------------|--------------------|------------|-------------|
| SLJR200            | 196008           | Stainless Steel 304 (EN 1.4301) | 1.5 mm             | 19 mm      | 12.7 mm     |

## ADDITIONAL PRODUCT DETAILS

The 1.5 mm locking devices are only to be used with the SLC15L1000SP and SLC15L50MSP wire spools, or any other 1.5 mm nVent CADDY Speed Link accessories. Do not use with any other wires.

DIAGRAMS

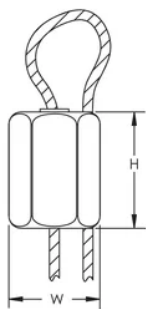

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europa

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europa

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**