



NVENT CADDY SPEED LINK SLK WITH TOGGLE



CERTIFICATIONS



CARACTERÍSTICAS

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Also available in Y-toggle configuration

SPECIFICATIONS

Wire Rope Diameter:	1,5 mm
Static Load Safety Factor:	5:1
Acabamento:	Eletro galvanizado
Material:	Steel; Zinc Alloy; Polypropylene
Em conformidade com:	SMACNA HVAC-DCS

Table 1/1

Número do catálogo	Número do artigo	Wire Rope Length	A	B	Carga estática (F)	Quantidade da embalagem
SLK15L10T	196526	10m	39 mm	5 mm	195N	1.0000

Número do catálogo	Número do artigo	Wire Rope Length	A	B	Carga estática (F)	Quantidade da embalagem
SLK15L1T	196521	1m	39 mm	5 mm	195N	1.0000
SLK15L2T	196522	2m	39 mm	5 mm	195N	1.0000
SLK15L2TR2	196644	2m	39 mm	5 mm	195N	2.0000
SLK15L3T	196523	3m	39 mm	5 mm	195N	1.0000
SLK15L5T	196524	5m	39 mm	5 mm	195N	1.0000
SLK15L7T	196525	7m	39 mm	5 mm	195N	1.0000


Espessura (T): 12.5 mm

Largura (W): 19 mm

Altura (H): 55 mm

Ângulo (a): 90 ° Max

DIAGRAMS

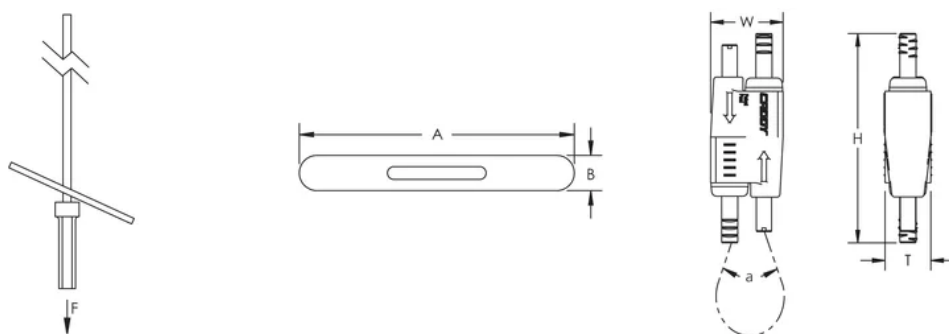

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europa

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europa

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER