

## NVENT CADDY MACROFIX PLUS KOMBI WITH COMBINATION NUT



### FEATURES

Includes easy closing mechanism

Age-resistant lining

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

### SPECIFICATIONS

**Rod Size (RS):** M8;M10;1/2"

**Color:** Black

**Finish:** Electrogalvanized

**Material:** Steel;EPDM-SBR Rubber

**Temperature:** -50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Width (W)	Thickness (T)
MPK031	586754	25 - 31 mm	3/4"	20	20 mm	1 mm
MPK037	586755	31 - 37 mm	1"	25	20 mm	1 mm
MPK044	586756	37 - 44 mm	1 1/4"	32	20 mm	1 mm
MPK051	586757	45 - 51 mm	1 1/2"	40	21 mm	1.25 mm
MPK058	586758	50 - 58 mm			21 mm	1.25 mm


Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Width (W)	Thickness(T)
MPK068	586759	58 - 68 mm	2" - 5"	50	21 mm	1.25 mm
MPK078	586760	68 - 78 mm	2 1/2"	65	23 mm	1.5 mm
MPK088	586761	78 - 88 mm			23 mm	1.5 mm
MPK098	586762	88 - 98 mm	3"	80	23 mm	1.75 mm
MPK118	586763	108 - 118 mm	4"	100	23 mm	1.75 mm
MPK138	586764	128 - 138 mm			23 mm	2 mm
MPK148	586765	138 - 148 mm	5"	125	25 mm	2 mm
MPK160	586766	150 - 160 mm			25 mm	2 mm
MPK170	586767	160 - 170 mm	6"	150	25 mm	2 mm
MPK201	586768	190 - 200 mm			27 mm	2.25 mm

Table 2/2					
Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)	Unit Weight
MPK031	586754	6 mm	32mm	1000N	0.11 kg
MPK037	586755	6 mm	32mm	1000N	0.12 kg
MPK044	586756	6 mm	37mm	1000N	0.12 kg
MPK051	586757	6 mm	37mm	1500N	0.14 kg
MPK058	586758	6 mm	37mm	1500N	0.15 kg
MPK068	586759	6 mm	40mm	1500N	0.16 kg
MPK078	586760	6 mm	40mm	2000N	0.19 kg
MPK088	586761	6 mm	40mm	2000N	0.2 kg
MPK098	586762	6 mm	45mm	2500N	0.27 kg
MPK118	586763	6 mm	50mm	2500N	0.3 kg
MPK138	586764	6 mm	50mm	3000N	0.34 kg
MPK148	586765	6 mm	50mm	3200N	0.4 kg
MPK160	586766	6 mm	50mm	3200N	0.42 kg
MPK170	586767	6 mm	50mm	3200N	0.42 kg
MPK201	586768	6 mm	50mm	3600N	0.63 kg

## ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

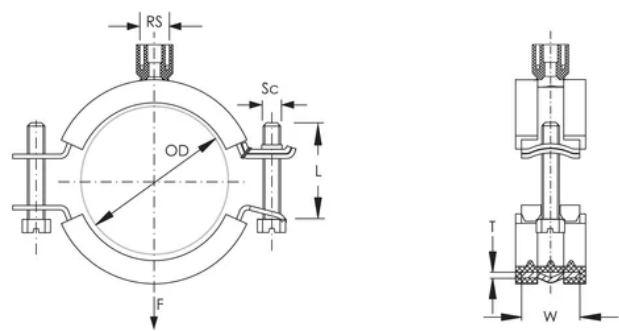

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**