

APY EXTERNAL HORIZONTAL WALL BRACKET



FEATURES

Side mount saddle support for C-Profiles and strut

Complete with fixings

SPECIFICATIONS

Finish: Electrogalvanized

Table 1/2


Catalog Number	Article Number	Material	Channel Type	Strut Type	Height (H)	Width (W)
APYE01EG	584758	Steel	E0L, E0, E1		40 mm	124 mm
APYE23EG	584740	Steel	E2L, E2, E3		40 mm	124 mm
APYE4STRUTEG	584751	Steel	E4	A (41 x 41 mm), C (21 x 41 mm)	50 mm	144 mm
APYSTRUTS6	584840	Stainless Steel 316 (EN 1.4401)		A (41 x 41 mm), C (21 x 41 mm)	50 mm	144 mm

Table 2/2

Catalog Number	Article Number	Thickness (T)	A	B	C
APYE01EG	584758	5 mm	31 mm	12 mm	19 mm
APYE23EG	584740	5 mm	36 mm	12 mm	19 mm
APYE4STRUTEG	584751	5 mm	43 mm	12 mm	19 mm

CatalogNumber	Article Number	Thickness (T)	A	B	C
APYSTRUTS6	584840	5 mm	43 mm	12 mm	19 mm

DIAGRAMS

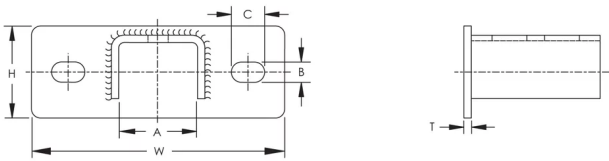

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500