



# NVENT CADDY SPEED LINK SLK WITH DECKING HOOK



## CERTIFICATIONS



## FEATURES

- Complete system includes wire, locking device and pre-assembled decking hook end fitting
- Quickly and easily attaches to hollow metal decking
- Spring-loaded ends snap into decking hole and lock into place
- Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire

## SPECIFICATIONS

- Static Load Safety Factor:** 5:1
- Finish:** Electrogalvanized
- Material:** Steel;Zinc Alloy;Polypropylene
- Complies With:** SMACNA HVAC-DCS

Table 1/2						
Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	Roof Decking Sheet Thickness	A	Hole Size (HS)
SLK15L1DH	196676	1.5 mm	1m	1.5 mm Max	9.2 mm	8 mm

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	RoofDecking Sheet Thickness	A	Hole Size (HS)
SLK15L2DH	196677	1.5 mm	2m	1.5 mm Max	9.2 mm	8 mm
SLK2L3DH	196532	2 mm	3m	1.5 mm Max	9.2 mm	8 mm
SLK2L5DH	196533	2 mm	5m	1.5 mm Max	9.2 mm	8 mm
SLK2L7DH	196534	2 mm	7m	1.5 mm Max	9.2 mm	8 mm

Table 2/2

Catalog Number	Article Number	Static Load (F)
SLK15L1DH	196676	195N
SLK15L2DH	196677	195N
SLK2L3DH	196532	440N
SLK2L5DH	196533	440N
SLK2L7DH	196534	440N

**Thickness (T):** 12.5 mm

**Width (W):** 19 mm

**Height (H):** 55 mm


**Angle (a):** 90 ° Max

## ADDITIONAL PRODUCT DETAILS

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

## DIAGRAMS

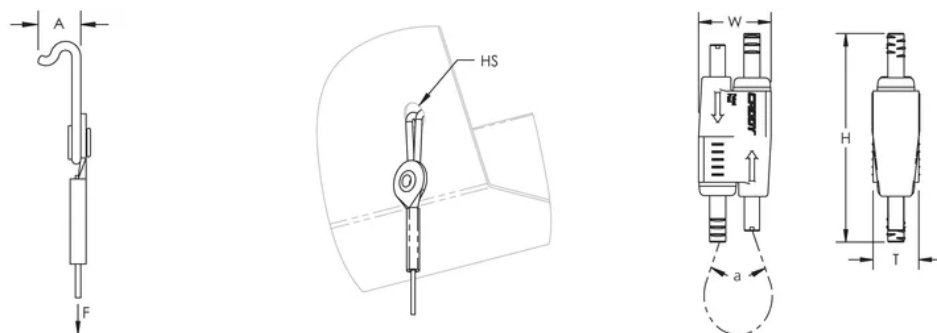

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**