

19" FRONT PANEL

Front panels are Al anodized, colours light grey (RAL 7035) or black grey (RAL 7021).



CERTIFICATIONS



FEATURES

Al anodized, 3 mm

SPECIFICATIONS

Аксессуар Тип: Front panel

Table 1/3

| Catalog Number | Type | Mounting | Front Finish | Rear Finish | Treated Edges | EMC Shielding |
|----------------|-----------------|----------------|--------------|-------------|---------------|---------------|
| 30118-299 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-948 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30219-098 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 40304-074 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 30118-301 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-302 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-303 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |

| Catalog Number | Type | Mounting | Front Finish | Rear Finish | Treated Edges | EMC Shielding |
|----------------|-----------------|----------------|--------------|-------------|---------------|---------------|
| 30118-304 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-305 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-306 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-307 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-308 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-309 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-949 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-950 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-951 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-952 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-953 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-954 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-955 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-956 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30118-957 | 19" Front Panel | Screw-on Front | Painted | Painted | | No |
| 30219-101 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-104 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-107 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-110 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-113 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-137 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-138 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-143 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 30219-144 | 19" Front Panel | Screw-on Front | Anodized | Anodized | No | No |
| 40304-075 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-076 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-077 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-078 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-079 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-080 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-081 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-082 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |
| 40304-083 | 19" Front Panel | Screw-on Front | Anodized | Anodized | Yes | No |

Table 2/3

| Catalog Number | Rack Width | Product Type | Высота мм (H) | Works With | Rack Height | Package Quantity |
|----------------|------------|--------------|---------------|-------------------------------------|-------------|------------------|
| 30118-299 | 95HP | Front Panel | 43.6mm | Cabinet, Wallmount Cases, 19" cases | 1U | 1 |
| 30118-948 | 95HP | Front Panel | 43.6mm | Cabinet, Wallmount Cases, 19" cases | 1U | 1 |
| 30219-098 | 95HP | Front Panel | 43.6mm | Cabinet, Wallmount Cases, 19" cases | 1U | 1 |
| 40304-074 | 95HP | Front Panel | 43.6mm | Cabinet, Wallmount Cases, 19" cases | 1U | 1 |
| 30118-301 | 95HP | Front Panel | 88.1mm | Cabinet, Wallmount Cases, 19" cases | 2U | 1 |
| 30118-302 | 95HP | Front Panel | 132.5mm | Cabinet, Wallmount Cases, 19" cases | 3U | 1 |
| 30118-303 | 95HP | Front Panel | 177mm | Cabinet, Wallmount Cases, 19" cases | 4U | 1 |
| 30118-304 | 95HP | Front Panel | 221.4mm | Cabinet, Wallmount Cases, 19" cases | 5U | 1 |
| 30118-305 | 95HP | Front Panel | 265.9mm | Cabinet, Wallmount Cases, 19" cases | 6U | 1 |
| 30118-306 | 95HP | Front Panel | 310.3mm | Cabinet, Wallmount Cases, 19" cases | 7U | 1 |
| 30118-307 | 95HP | Front Panel | 354.8mm | Cabinet, Wallmount Cases, 19" cases | 8U | 1 |

| Catalog Number | Rack Width | ProductType | Высота мм (H) | Works With | Rack Height | Package Quantity |
|----------------|------------|-------------|---------------|-------------------------------------|-------------|------------------|
| 30118-308 | 95HP | Front Panel | 399.2mm | Cabinet, Wallmount Cases, 19" cases | 9U | 1 |
| 30118-309 | 95HP | Front Panel | 443.7mm | Cabinet, Wallmount Cases, 19" cases | 10U | 1 |
| 30118-949 | 95HP | Front Panel | 88.1mm | Cabinet, Wallmount Cases, 19" cases | 2U | 1 |
| 30118-950 | 95HP | Front Panel | 132.5mm | Cabinet, Wallmount Cases, 19" cases | 3U | 1 |
| 30118-951 | 95HP | Front Panel | 177mm | Cabinet, Wallmount Cases, 19" cases | 4U | 1 |
| 30118-952 | 95HP | Front Panel | 221.4mm | Cabinet, Wallmount Cases, 19" cases | 5U | 1 |
| 30118-953 | 95HP | Front Panel | 265.9mm | Cabinet, Wallmount Cases, 19" cases | 6U | 1 |
| 30118-954 | 95HP | Front Panel | 310.3mm | Cabinet, Wallmount Cases, 19" cases | 7U | 1 |
| 30118-955 | 95HP | Front Panel | 354.8mm | Cabinet, Wallmount Cases, 19" cases | 8U | 1 |
| 30118-956 | 95HP | Front Panel | 399.2mm | Cabinet, Wallmount Cases, 19" cases | 9U | 1 |
| 30118-957 | 95HP | Front Panel | 443.7mm | Cabinet, Wallmount Cases, 19" cases | 10U | 1 |

| Catalog Number | Rack Width | ProductType | Высота мм (H) | Works With | Rack Height | Package Quantity |
|----------------|------------|-------------|---------------|-------------------------------------|-------------|------------------|
| 30219-101 | 95HP | Front Panel | 88.1mm | Cabinet, Wallmount Cases, 19" cases | 2U | 1 |
| 30219-104 | 95HP | Front Panel | 132.5mm | Cabinet, Wallmount Cases, 19" cases | 3U | 1 |
| 30219-107 | 95HP | Front Panel | 177mm | Cabinet, Wallmount Cases, 19" cases | 4U | 1 |
| 30219-110 | 95HP | Front Panel | 221.4mm | Cabinet, Wallmount Cases, 19" cases | 5U | 1 |
| 30219-113 | 95HP | Front Panel | 265.9mm | Cabinet, Wallmount Cases, 19" cases | 6U | 1 |
| 30219-137 | 95HP | Front Panel | 310.3mm | Cabinet, Wallmount Cases, 19" cases | 7U | 1 |
| 30219-138 | 95HP | Front Panel | 354.8mm | Cabinet, Wallmount Cases, 19" cases | 8U | 1 |
| 30219-143 | 95HP | Front Panel | 399.2mm | Cabinet, Wallmount Cases, 19" cases | 9U | 1 |
| 30219-144 | 95HP | Front Panel | 443.7mm | Cabinet, Wallmount Cases, 19" cases | 10U | 1 |
| 40304-075 | 95HP | Front Panel | 88.1mm | Cabinet, Wallmount Cases, 19" cases | 2U | 1 |
| 40304-076 | 95HP | Front Panel | 132.5mm | Cabinet, Wallmount Cases, 19" cases | 3U | 1 |

| Catalog Number | Rack Width | ProductType | Высота мм (H) | Works With | Rack Height | Package Quantity |
|----------------|------------|-------------|---------------|-------------------------------------|-------------|------------------|
| 40304-077 | 95HP | Front Panel | 177mm | Cabinet, Wallmount Cases, 19" cases | 4U | 1 |
| 40304-078 | 95HP | Front Panel | 221.4mm | Cabinet, Wallmount Cases, 19" cases | 5U | 1 |
| 40304-079 | 95HP | Front Panel | 265.9mm | Cabinet, Wallmount Cases, 19" cases | 6U | 1 |
| 40304-080 | 95HP | Front Panel | 310.3mm | Cabinet, Wallmount Cases, 19" cases | 7U | 1 |
| 40304-081 | 95HP | Front Panel | 354.8mm | Cabinet, Wallmount Cases, 19" cases | 8U | 1 |
| 40304-082 | 95HP | Front Panel | 399.2mm | Cabinet, Wallmount Cases, 19" cases | 9U | 1 |
| 40304-083 | 95HP | Front Panel | 443.7mm | Cabinet, Wallmount Cases, 19" cases | 10U | 1 |


| Table 3/3 | | | | | | |
|----------------|---------------|----------|------------|------------|---------------|----------------|
| Catalog Number | Finish | Material | Color | Color Code | Ширина мм (W) | Глубина мм (D) |
| 30118-299 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-948 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30219-098 | Anodized | Aluminum | | | 483mm | 3mm |
| 40304-074 | Anodized | Aluminum | | | 483mm | 4mm |
| 30118-301 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-302 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-303 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-304 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-305 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-306 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |

| Catalog Number | Finish | Material | Color | Color Code | Ширина мм (W) | Глубина мм (D) |
|----------------|---------------|----------|------------|------------|---------------|----------------|
| 30118-307 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-308 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-309 | Powder Coated | Aluminum | Light Grey | RAL 7035 | 483mm | 3mm |
| 30118-949 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-950 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-951 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-952 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-953 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-954 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-955 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-956 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30118-957 | Powder Coated | Aluminum | Black Grey | RAL 7021 | 483mm | 3mm |
| 30219-101 | Anodized | Aluminum | | | 483mm | 3mm |
| 30219-104 | Anodized | Aluminum | | | 483mm | 3mm |
| 30219-107 | Anodized | Aluminum | | | 483mm | 3mm |
| 30219-110 | Powder Coated | Aluminum | | | 483mm | 3mm |
| 30219-113 | Anodized | Aluminum | | | 483mm | 3mm |
| 30219-137 | Anodized | Aluminum | | | 483mm | 3mm |
| 30219-138 | Anodized | Aluminum | | | 483mm | 3mm |
| 30219-143 | Anodized | Aluminum | | | 483mm | 3mm |
| 30219-144 | Anodized | Aluminum | | | 483mm | 3mm |
| 40304-075 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-076 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-077 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-078 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-079 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-080 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-081 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-082 | Anodized | Aluminum | | | 483mm | 4mm |
| 40304-083 | Anodized | Aluminum | | | 483mm | 4mm |

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

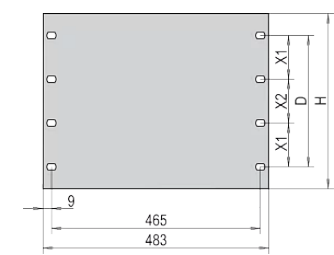

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER