

SURGE COUNTER, MECHANICAL DISPLAY




FEATURES

Provides a non-resettable record of the number of surges diverted

SPECIFICATIONS

Catalog Number	TDSSC
Article Number	701250
Trip Threshold	300
Connection, Solid	1 - 6 mm ²
Connection, Stranded	1 - 6 mm ²
Enclosure Material	UL® 94V-0 Thermoplastic
Enclosure Rating	IP 20 NEMA®-1
Mounting	35 mm top hat DIN rail
Temperature	-35 to 55 °C
Module Width	2 M
Depth (D)	68mm
Height (H)	90 mm
Width (W)	36 mm
Unit Weight	0.2 kg

DIAGRAMS

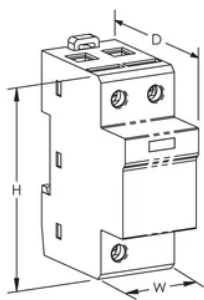

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com **CADDY** **ERICO** **HOFFMAN** **RAYCHEM** **SCHROFF**

TRACER