


ПЕРЕДНЯЯ РУЧКА, ЦЕЛЬНАЯ, ШИРИНА 12,2 ММ

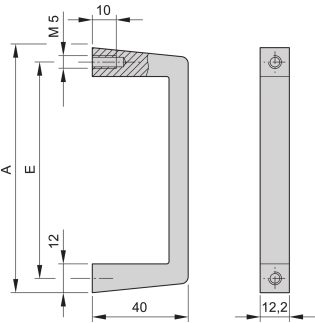

Ручка может крепиться к блочному каркасу или 19-дюймовой передней панели. Поставляется с прозрачным или черным анодным покрытием. Ручки крепятся болтами с задней стороны.

CERTIFICATIONS



FEATURES

- Допустимая статическая нагрузка 30 кг/пара
- Привинчивается сзади

SPECIFICATIONS

Table 1/2						
Catalog Number	Product Type	Works With	Handle Type	Rack Height	Material	Color
10501-116	Handle	Subracks	Straight	1U	Aluminum	Silver
10501-004	Handle	Subracks	Straight	2U	Aluminum	Silver
10501-005	Handle	Subracks	Straight	3U	Aluminum	Silver
10501-006	Handle	Subracks	Straight	4U	Aluminum	Silver
10501-007	Handle	Subracks	Straight	5U	Aluminum	Silver
10501-008	Handle	Subracks	Straight	6U	Aluminum	Silver
10501-016	Handle	Subracks	Straight	2U	Aluminum	Silver
10501-018	Handle	Subracks	Straight	4U	Aluminum	Silver

Catalog Number	ProductType	Works With	Handle Type	Rack Height	Material	Color
10501-020	Handle	Subracks	Angled Handle	3U	Aluminum	Silver
10501-021	Handle	Subracks	Angled Handle	4U	Aluminum	Silver
10501-022	Handle	Subracks	Angled Handle	6U	Aluminum	Silver
10501-025	Handle	Subracks	Straight	2U	Aluminum	Black
10501-026	Handle	Subracks	Straight	3U	Aluminum	Black
10501-027	Handle	Subracks	Straight	4U	Aluminum	Black
10501-028	Handle	Subracks	Straight	5U	Aluminum	Black
10501-029	Handle	Subracks	Straight	6U	Aluminum	Black

Table 2/2			
Catalog Number	Package Quantity	Finish	Torque
10501-116	1	Anodized	
10501-004	1	Anodized	
10501-005	1	Anodized	2.4N·m
10501-006	1	Anodized	
10501-007	1	Anodized	
10501-008	1	Anodized	2.4N·m
10501-016	1	Anodized	
10501-018	1	Anodized	2.4N·m
10501-020	1	Anodized	2.4N·m
10501-021	1	Anodized	2.4N·m
10501-022	1	Anodized	2.4N·m
10501-025	1	Anodized	
10501-026	1	Anodized	2.4N·m
10501-027	1	Anodized	
10501-028	1	Anodized	
10501-029	1	Anodized	2.4N·m

ADDITIONAL PRODUCT DETAILS

Заказывайте комплект для сборки отдельно.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER