


## CRIMPING COMPRESSION TOOL DIE, TYPE ML, HEAVY-DUTY DIN46235, 120 MM<sup>2</sup> STRANDED, 250 KCMIL STRANDED

### CATALOG NUMBER

**PKML120**

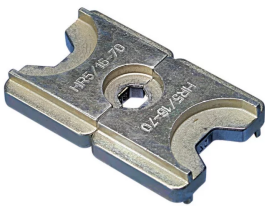

### FEATURES

Suitable for cable lugs and connectors

### PRODUCT ATTRIBUTES

Article Number: 716996

Kabelsko tilkoblingsmetode: Heavy-Duty DIN46235

Ledertverrsnitt: 120 mm<sup>2</sup> Stranded; 250 kcmil Stranded

Krympebredde: 5mm

Tool: MLB

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**