
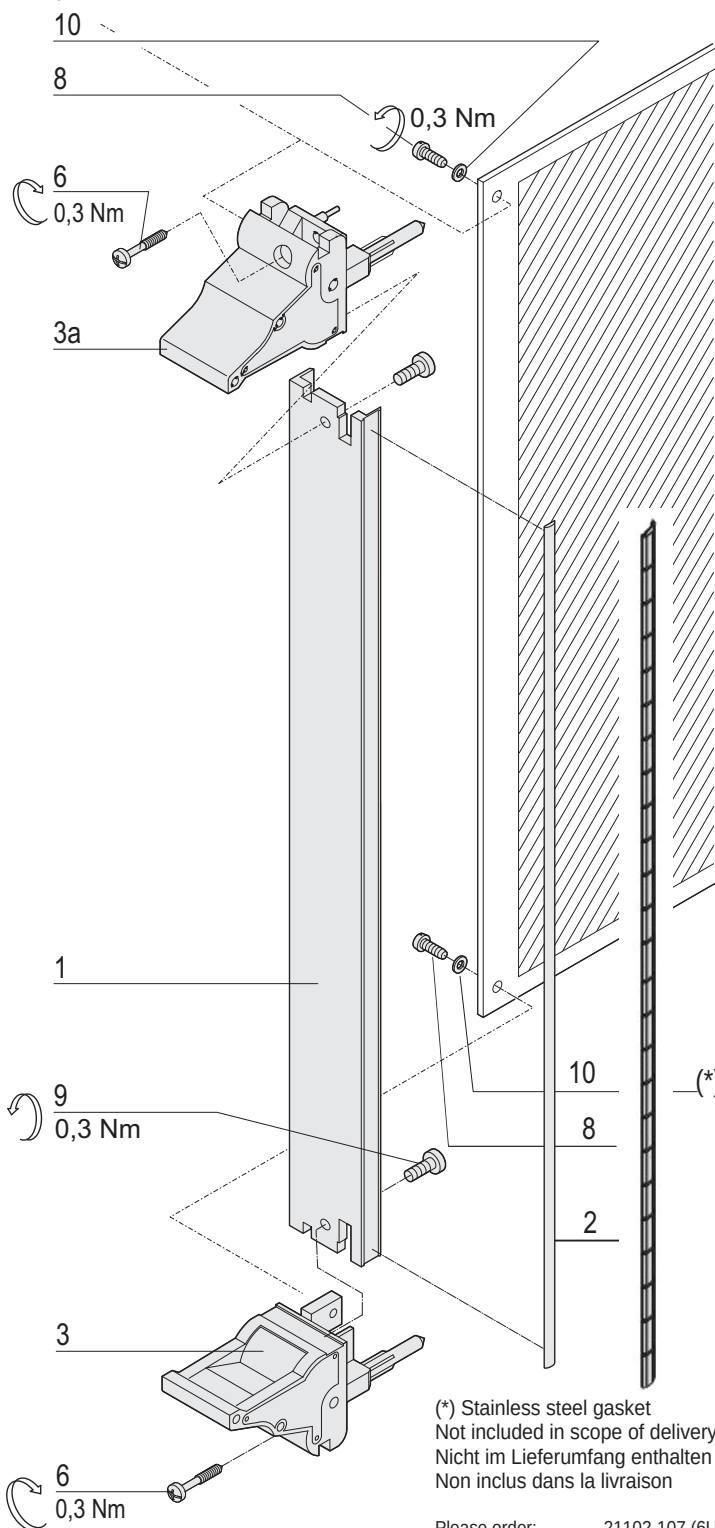



6 HE / 6 U

≥ 8 TE
≥ 8 HP
≥ 8 F

< 8 TE
< 8 HP
< 8 F

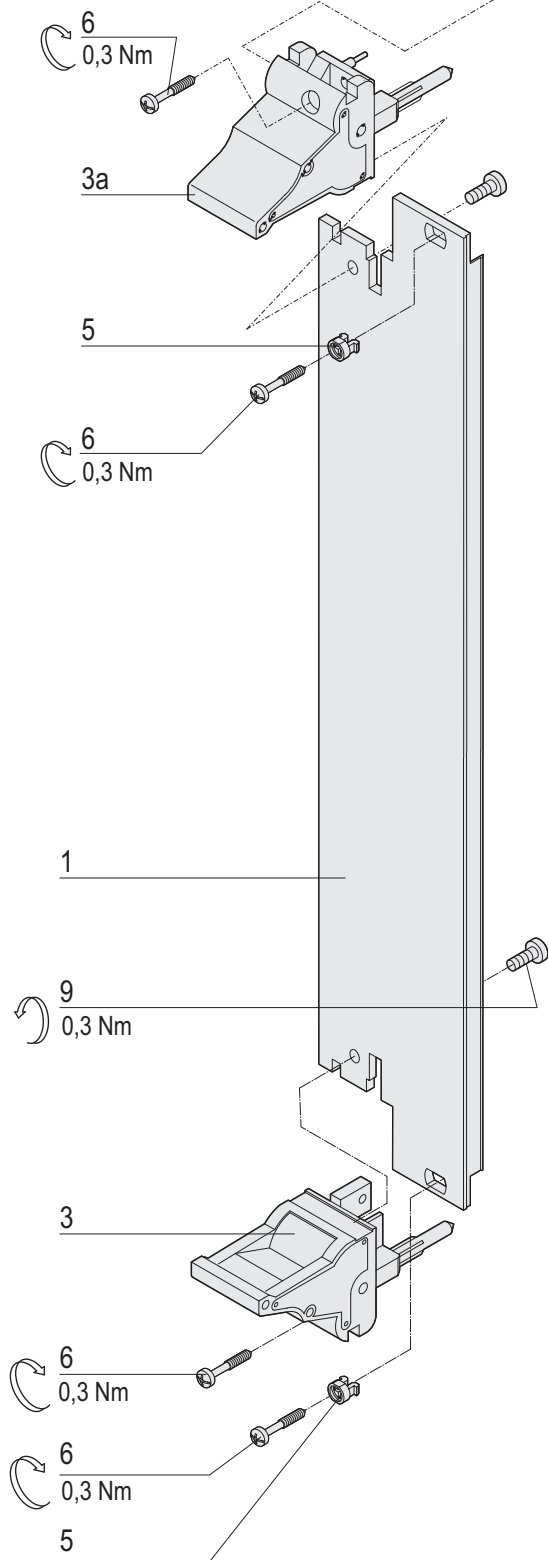

Please order: 21102-107 (6U)
Bitte bestellen Sie: 21102-107 (6HE)
Veuillez commander: 21102-107 (6U)

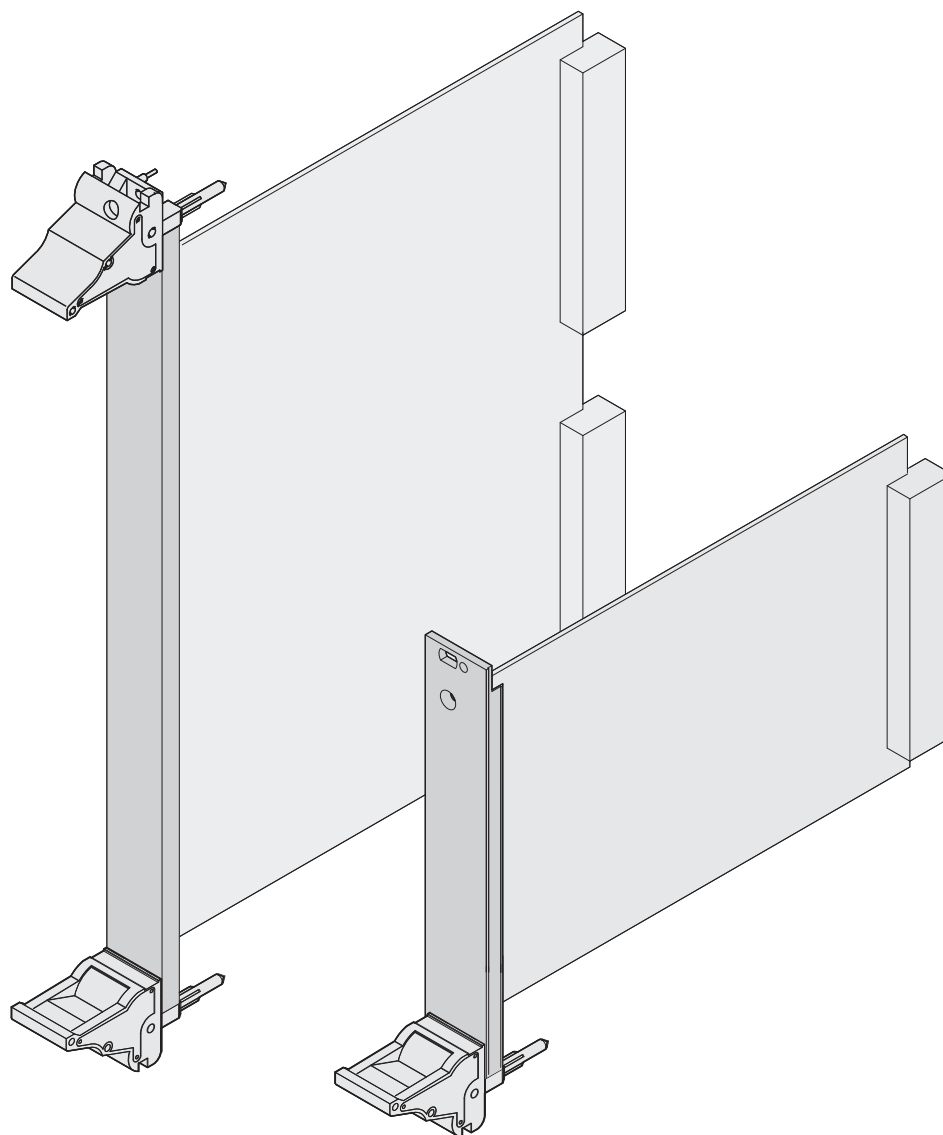

08/2023

ungeschirmt unshielded non blindé				geschirmt shielded blindé			
3 HE / 3 U		6 HE / 6 U		3 HE / 3 U		6 HE / 6 U	
< 8 TE < 8 HP < 8 F	≥ 8 TE ≥ 8 HP ≥ 8 F	< 8 TE < 8 HP < 8 F	≥ 8 TE ≥ 8 HP ≥ 8 F	< 8 TE < 8 HP < 8 F	≥ 8 TE ≥ 8 HP ≥ 8 F	< 8 TE < 8 HP < 8 F	≥ 8 TE ≥ 8 HP ≥ 8 F
Pos. Item Rep.							
1	1x	1x	1x	1x	1x	1x	1x
2	-	-	-	-	1x	1x	1x
3	1x	1x	1x	1x	1x	1x	1x
3a	-	-	1x	1x	-	-	1x
4	1x	1x	-	-	1x	1x	-
5	1x	3x	-	2x	1x	3x	-
6	2x	4x	2x	4x	2x	4x	2x
7	1x	1x	-	-	1x	1x	-
8	2x	2x	2x	2x	2x	2x	2x
9	1x	1x	2x	2x	1x	1x	2x
10	2x	2x	2x	2x	2x	2x	2x

2

3a

3

4

5

6
M2,5
x
12,3

7
M2,5
x
8,0

8
M2,5
x
6,0

9
M2,5
x
7,0

10
A 2,7

Halsschraube
Collar screw
Vis à gorge

Zentrierpin
Alignment pin
Pion de centrage

6

L

L = 12,3



L = 12,3

L = 12,3

3 HE / 3 U

≥ 8 TE
≥ 8 HP
≥ 8 F

< 8 TE
< 8 HP
< 8 F

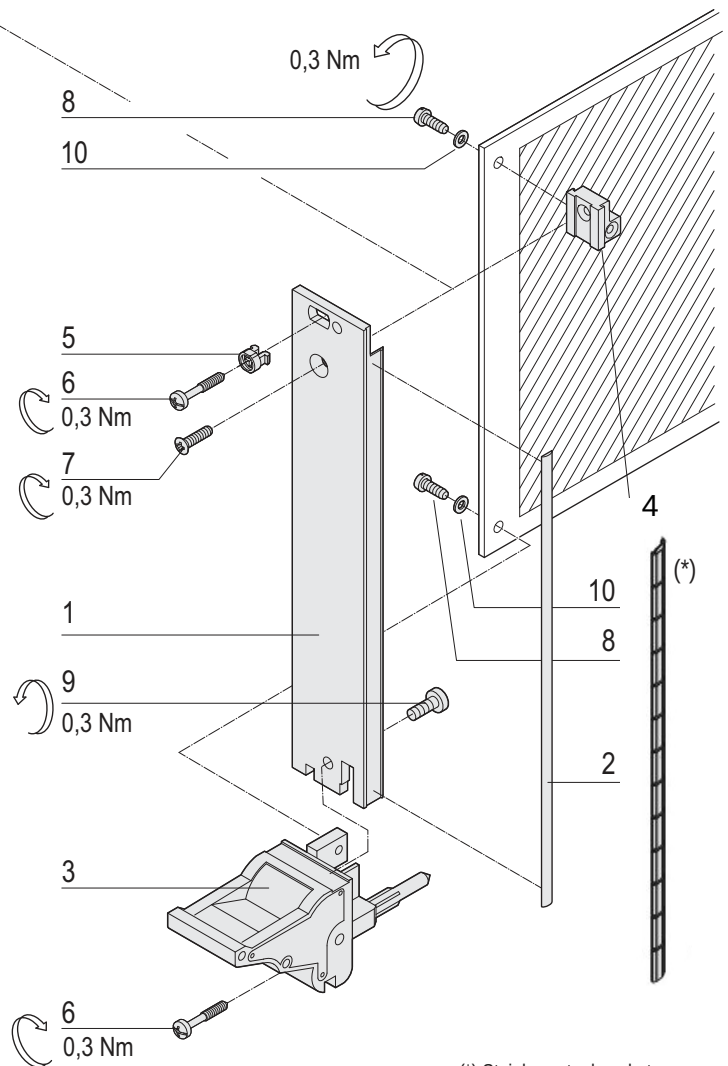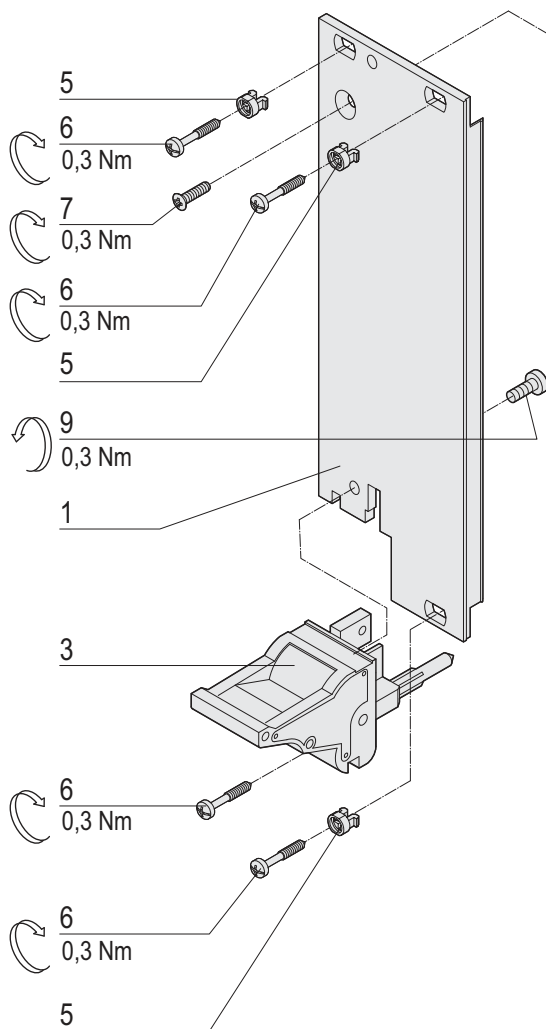

(*) Stainless steel gasket
Not included in scope of delivery
Nicht im Lieferumfang enthalten
Non inclus dans la livraison

Please order: 21102-105 (3U)
Bitte bestellen Sie: 21102-105 (3HE)
Veuillez commander: 21102-105 (3U)