


# nVent CADDY All-in-One Adjustable Mud Ring

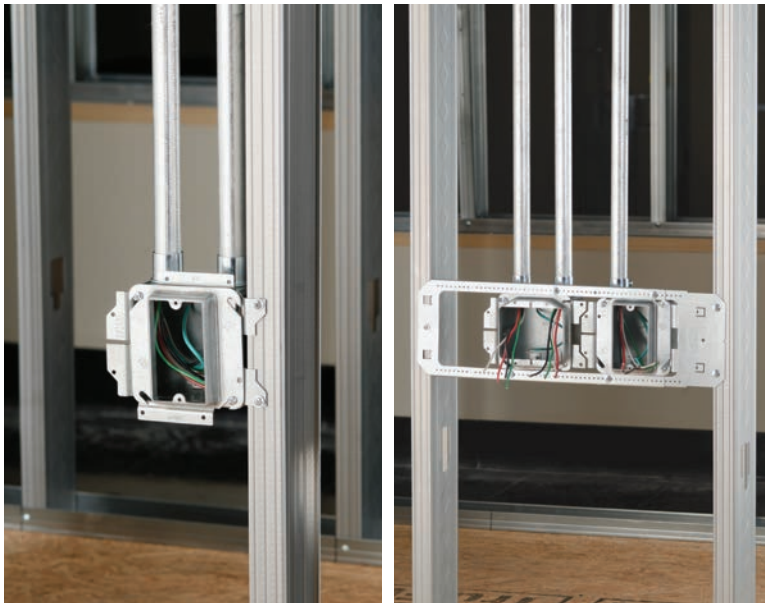


nVent CADDY All-in-One Electrical Assemblies provide contractors with a quick and simple way to mount, wire and install electrical devices. Whether on the job or off-site, installers can utilize one system to meet several different requirements and unique preferences.

By combining electrical boxes with support brackets, mud rings, far-side support and ground wire pigtails, nVent CADDY has created an out-of-the-box, ready-to-use solution to meet your project's needs. Enjoy enhanced flexibility and easier access due to the open-back box design. Contractors can have peace of mind knowing nVent CADDY solutions are designed to be safe, fast and easy.

- Adjustable mud ring accommodates various thicknesses of drywall
- Can be adjusted after installation of drywall
- Box remains fixed in place when mud ring is removed

## NVENT CADDY ALL-IN-ONE STUD-MOUNTED WITH ADJUSTABLE MUD RING

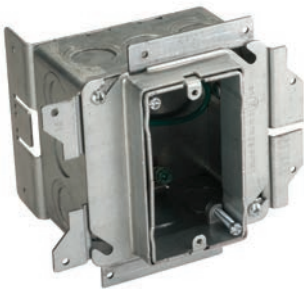

- Includes multiple knockouts on each side of the box
- Assemblies keyed for precise alignment when installed on both sides of a stud

Material: Steel  
Finish: Pregalvanized  
Knockout Sizes: (8) 1/2", 3/4", (3) 1/2"



Part Number	Gang	Ground Wire Included	Back Plate Pre-assembled	Box Volume	Drywall Thickness	Depth	Width	Window Height
A1SFV1G	1	Yes	Yes	32.8 in <sup>3</sup>	3/4" – 1 1/2"	3 5/8"	5 3/4"	5 1/8"
A1SFV1GS	1	Yes	Yes	32.8 in <sup>3</sup>	3/4" – 1 1/2"	2 1/2"	5 3/4"	5 1/8"
A1SFV2G	2	Yes	Yes	32.8 in <sup>3</sup>	5/8" – 1 1/2"	3 5/8"	5 3/4"	5 1/8"
A1SFV2GS	2	Yes	Yes	32.8 in <sup>3</sup>	5/8" – 1 1/2"	2 1/2"	5 3/4"	5 1/8"

Ground wire pigtail is 10".

## NVENT CADDY ALL-IN-ONE BETWEEN-STUD WITH ADJUSTABLE MUD RING



- Comes with multiple boxes pre-assembled for side by side power and data applications
- Pre-bent tabs on support bracket help to quickly square assembly to stud
- Center marks provide easy height positioning
- Includes multiple knockouts on each side of the box

Material: Steel | Finish: Pregalvanized

Knockout Sizes (Single) Box: (8) ½", ¾", (3) ½"

Knockout Sizes, (Multi) Box 1: (8) ½", ¾", (3) ½"

Knockout Sizes, (Multi) Box 2: (5) ½", ¾", (1) ½", (3) 1"



Part Number	Gang	Ground Wire Included		Box Volume	Drywall Thickness	Stud Spacing	Depth	Height	Window Height
		Box 1	Box 2						
Single Box									
A1BFV1GS	1	Yes		32.8 in³	¾" – 1 ½"	16" – 24"	2 ½"	5 ¾"	4 ⅛"
A1BFV1G	1	Yes		32.8 in³	¾" – 1 ½"	16" – 24"	3 ⅝"	5 ¾"	4 ⅛"
Multi Box									
A1BFV1GDV1NS	1	Yes	Yes	32.8 in³	¾" – 1 ½"	16" – 24"	2 ½"	5 ¾"	4 ⅛"
A1BFV1GDV1N	1	Yes	Yes	32.8 in³	¾" – 1 ½"	16" – 24"	3 ⅝"	5 ¾"	4 ⅛"
A1BFV1GFV1N	1	Yes	Yes	32.8 in³	¾" – 1 ½"	16" – 24"	3 ⅝"	5 ¾"	4 ⅛"

Ground wire pigtail is 10". 24" stud spacing requires use of three mounting screws. Use only with nVent CADDY All-in-One box assemblies.

## NVENT CADDY ALL-IN-ONE FLOOR-MOUNTED WITH ADJUSTABLE MUD RING



- Preset to a finish height of 18 in from the floor (adjustable to 12 or 15 in)
- Integrated first means of support accepts conduit or MC/AC cable
- Accommodates additional nVent CADDY All-in-One box assemblies, support brackets and low-voltage mounting plates
- Includes multiple ½ and ¾ in knockouts on each side of the box

Material: Steel

Finish: Pregalvanized

EMT Conduit Size: ½", ¾"

MC/AC Cable Size: 14-2 to 12-3

Knockout Sizes: (8) ½", ¾", (3) ½"



Part Number	Gang	Ground Wire Included	Box Volume	Drywall Thickness	Stud Depth	Height	Width	Depth
A1FFV1G	1	Yes	32.8 in³	¾" – 1 ½"	3 ⅝"	22 ⅜"	7 ¾"	2 ⅜"
A1FFV2G	2	Yes	32.8 in³	5/8" – 1 ½"	3 ⅝"	22 ⅜"	7 ¾"	2 ⅜"



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

RAYCHEM

SCHROFF