


FOUR POLE DISTRIBUTION BLOCK WITH THREADED BARS, FLAT, 630 A

KATALOGNUMMER

TRC-630A

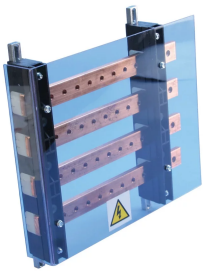

CERTIFICATIONS



DESIGN

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

PRODUKTATTRIBUT

Article Number: 563190

Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (I_{pk}): 84kA

Short Term Withstand Current (I_{cw}) 1s: 52kA

Line Side Number of Connections: 1

Load Side Number of Connections: 8

Håldimension (HS): 10mm

Gångstorlek (TS): M8

Djup (D): 60mm

Höjd (H): 338 – 390mm

Bredd (W): 340mm

A: 290mm

Enhetsvikt: 4.8kg


Flammability Rating: UL® 94V-0

Uppfyller kraven enligt: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

DIAGRAMS

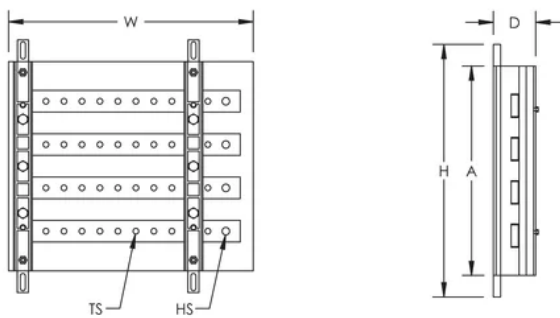

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER