


TELECOM GROUNDING BUSBAR

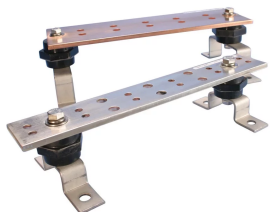

CERTIFICATIONS



DESIGN

Meets TIA-607-C and TIA-607-D conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

SPECIFIKATIONER

Tjocklek (T): 6.35mm

Bredd (W): 50.8mm

Material: Copper

Table 1/2


Katalognum mer	Längd 1 (L1)	Längd 2 (L2)	Tennpläterin g	Hålstorlek 1 antal par	Hålstorlek 2 antal par	C
TGBA12L06P	305mm	229mm	No	6	3	15.9mm
TGBA12L06PT	305mm	229mm	Yes	6	3	15.9mm
TGBA20L12PT	508mm	229mm	Yes	12	3	15.9mm

Katalognummer	Längd 1 (L1)	Längd 2 (L2)	Tennplätering	Hålstorlek 1 antal par	Hålstorlek 2 antal par	C
TGBA24L14P	610mm	457mm	No	14	5	15.9mm
TGBA24L14PT	610mm	457mm	Yes	14	5	15.9mm
TGBA29L18PT	737mm	457mm	Yes	18	5	15.9mm

Table 2/2

Katalognummer	B	A	Håldimension 1 (HS1)	Håldimension 2 (HS2)
TGBA12L06P	28.6mm	25.4mm	8mm	11mm
TGBA12L06PT	28.6mm	25.4mm	8mm	11mm
TGBA20L12PT	28.6mm	25.4mm	8mm	11mm
TGBA24L14P	28.6mm	25.4mm	8mm	11mm
TGBA24L14PT	28.6mm	25.4mm	8mm	11mm
TGBA29L18PT	28.6mm	25.4mm	8mm	11mm

 DIAGRAMS



WARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER