


TR FOUR POLE DISTRIBUTION BLOCK, 400 A

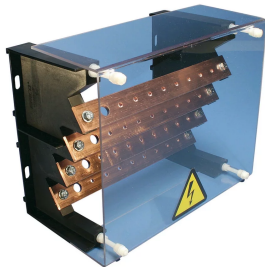

CERTIFICATIONS



DESIGN

Easily fixes onto DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKATIONER

Table 1/3

Katalognummer	Article Number	Peak Short Circuit Current (I _{pk})	Material	Short Term Withstand Current (I _{cw}) 1s	Line Side Number of Connections	Load Side Number of Connections
TR-400A	562010	34kA	Copper, Glass Fibre Reinforced Polyamide, Plexiglass	28kA	1	8

Table 2/3

Katalognummer	Article Number	Gångstorlek (TS)	Max Working Voltage, IEC (Ui)	Håldimension (HS)	Höjd (H)	Bredd (W)
TR-400A	562010	M6	1000	10mm	240mm	300mm


Table 3/3

Katalognummer	Article Number	Djup (D)	Enhetsvikt	Flammability Rating	Uppfyller kraven enligt
TR-400A	562010	140mm	2.83kg	UL® 94V-0	IEC® 60439.1, IEC® 61439.1, IEC® 60695-2-11 (Glow Wire Test 960 °C)

ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

DIAGRAMS

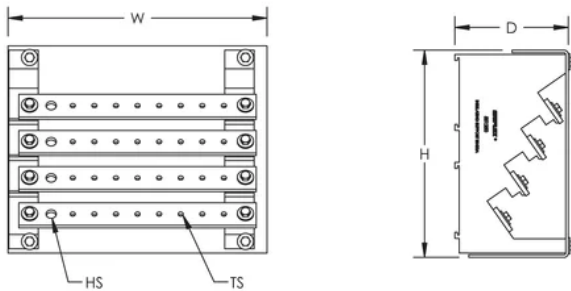

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER