


MOUNTING PLATE FOR 19" CASE AND SUBRACK

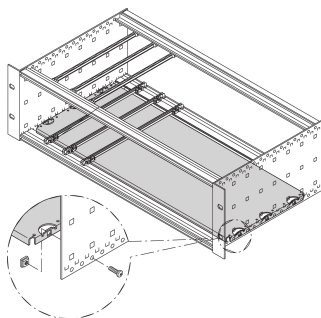

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICATIONS



FEATURES

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

SPECIFICATIONS

Table 1/2

Katalognummer	Rack Width	Package Quantity	Product Type	Product Family	Fungerarmed	Bredd
34562-752	84 HP	1	Mounting Plate	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	Subracks	431.35 mm
34562-756	84 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	431.35 mm

Katalognummer	Rack Width	Package Quantity	ProductType	Product Family	Fungerar med	Bredd
34562-760	84 HP	1	Mounting Plate	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	Subracks	431.35 mm
34562-748	84 HP	1	Mounting Plate	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	Subracks	324.67 mm
34562-870	84 HP	1	Mounting Plate	EuropacPRO	Subracks	431.35 mm
34562-871	84 HP	1	Mounting Plate	EuropacPRO	Subracks	431.35 mm
34562-745	28 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	146.88 mm
34562-746	42 HP	1	Mounting Plate	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	Subracks	217.99 mm
34562-747	63 HP	1	Mounting Plate	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	Subracks	324.67 mm
34562-749	28 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	146.88 mm
34562-750	42 HP	1	Mounting Plate	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	Subracks	217.99 mm
34562-751	63 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO	Subracks	324.67 mm
34562-753	28 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	146.88 mm
34562-754	42 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	217.99 mm
34562-755	63 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	324.67 mm
34562-757	28 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	146.88 mm

Katalognummer	Rack Width	Package Quantity	ProductType	Product Family	Fungerar med	Bredd
34562-758	42 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	217.99 mm
34562-759	63 HP	1	Mounting Plate	EuropacPRO, RatiopacPRO, CompacPRO	Subracks	324.67 mm

Table 2/2			
Katalognummer	Djup	Material	Certifiering
34562-752	172.5 mm	Aluminium	RoHS
34562-756	232.5 mm	Aluminium	RoHS
34562-760	292.5 mm	Aluminium	RoHS
34562-748	112.5 mm	Aluminium	RoHS
34562-870	352.5 mm	Aluminium	
34562-871	412.5 mm	Aluminium	
34562-745	112.5 mm	Aluminium	RoHS
34562-746	112.5 mm	Aluminium	RoHS
34562-747	112.5 mm	Aluminium	RoHS
34562-749	172.5 mm	Aluminium	RoHS
34562-750	172.5 mm	Aluminium	RoHS
34562-751	172.5 mm	Aluminium	RoHS
34562-753	232.5 mm	Aluminium	RoHS
34562-754	232.5 mm	Aluminium	RoHS
34562-755	232.5 mm	Aluminium	RoHS
34562-757	292.2 mm	Aluminium	RoHS
34562-758	292.2 mm	Aluminium	RoHS
34562-759	292.2 mm	Aluminium	RoHS

ADDITIONAL PRODUCT DETAILS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk,

felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER