




NVENT CADDY CUSHION CLAMP INSULATED STRUT CLAMP FOR PIPE/TUBE

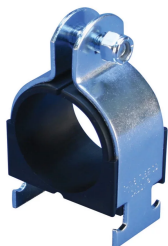

功能

Fits into open side of strut channel

Plastic cushion is hinged to spread apart for easy installation

Reduces noise and absorbs shock by gripping the pipe/tube firmly

Square neck of carriage bolt prevents over-tightening

Nylon locknut prevents loosening under vibration

FM® Specification Tested (from 3/8" to 4" of Copper Tube Size)

SPECIFICATIONS

材料: Steel;Polypropylene

表面处理: Zinc Chromate

Table 1/2


物料号	商品号	外径 (OD)	Copper Tube Size	管道尺寸	NB/DN	宽度 (W)
CCC0025	598882	6.3 mm				39.7 mm
CCC0037	598883	9.5 mm	1/4"			39.7 mm
CCC0050	598884	12.7 mm	3/8"	1/4"	8	39.7 mm

物料号	商品号	外径 (OD)	Copper Tube Size	管道尺寸	NB/DN	宽度 (W)
CCC0062	598886	15.8 mm	1/2"	3/8"	10	39.7 mm
CCC0087	598891	22.2 mm	3/4"	1/2"	15	39.7 mm
CCC0075	598888	19.1 mm	5/8"			39.7 mm
CCC0100	598892	25.4 mm		3/4"	20	39.7 mm
CCC0112	598894	28.6 mm	1"			39.7 mm
CCC0125	598895	31.8 mm		1"	25	39.7 mm
CCC0137	598897	34.9 mm	1 1/4"			39.7 mm
CCC0162	598899	41.3 mm	1 1/2"	1 1/4"	32	39.7 mm
CCC0150	598898	38.1 mm				39.7 mm
CCC0187	598903	47.6 mm		1 1/2"	40	39.7 mm
CCC0212	598906	53.9 mm	2"			39.7 mm
CCC0237	598908	60.3 mm		2"	50	39.7 mm
CCC0262	598941	66.7 mm	2 1/2"			39.7 mm
CCC0312	598945	79.4 mm	3"			39.7 mm
CCC0412	598953	104.8 mm	4"			39.7 mm
CCC0450	598957	114.3 mm		4"	100	39.7 mm

Table 2/2			
物料号	商品号	A	B
CCC0025	598882	15.7 mm	32.2 mm
CCC0037	598883	18.9 mm	35.4 mm
CCC0050	598884	22.1 mm	38.6 mm
CCC0062	598886	25.2 mm	41.7 mm
CCC0087	598891	31.6 mm	48.1 mm
CCC0075	598888	28.4 mm	44.9 mm
CCC0100	598892	34.8 mm	51.3 mm
CCC0112	598894	39 mm	62.4 mm
CCC0125	598895	42.1 mm	65.6 mm
CCC0137	598897	45.3 mm	68.8 mm
CCC0162	598899	51.6 mm	75.1 mm

物料号	商品号	A	B
CCC0150	598898	48.5 mm	72 mm
CCC0187	598903	59 mm	81.5 mm
CCC0212	598906	68.5 mm	91 mm
CCC0237	598908	74.9 mm	97.4 mm
CCC0262	598941	81.2 mm	103.7 mm
CCC0312	598945	93.9 mm	116.4 mm
CCC0412	598953	122.5 mm	151 mm
CCC0450	598957	132 mm	160.5 mm

DIAGRAMS

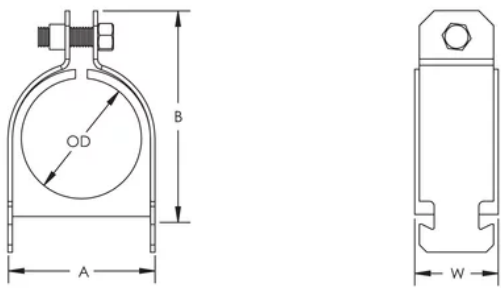

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美 +1.800.753.9221 Option 1 - Customer Care Option 2 - Technical Support	欧洲 Netherlands: +31 800-0200135 France: +33 800 901 793	欧洲 Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--