



STRUT NUT WITHOUT SPRING



功能

Used to create metal frames with nVent CADDY Eristrut channels

SPECIFICATIONS

Static Load Safety Factor: 3:1


材料: 钢

Table 1/1

物料号	商品号	表面处理	棒尺寸 (RS)	厚度 (T)	扭矩 (TQ)
NUTM6HD	315000	热浸镀锌	6	6 mm	12 N · m
NUTM8HD	315010	热浸镀锌	8	6 mm	28 N · m
NUTM10EG	315025	电镀锌	10	8 mm	55 N · m
NUTM12EG	315035	电镀锌	12	8 mm	55 N · m
NUTM12HD	315030	热浸镀锌	12	8 mm	55 N · m

Pull-Out Strength				
部件编号	Channel Type	Channel Thickness		
		2,5 mm	2 mm	1,5 mm
NUTM6xx	A, C	2000 N	2000 N	2000 N
	D, E	2000 N	-	-
NUTM8xx	A, C	3330 N	3330 N	3330 N
	D, E	3330 N	-	-
NUTM10xx	A, C	4890 N	4440 N	4440 N
	D, E	4890 N	-	-
NUTM12xx	A, C	4890 N	4660 N	4440 N
	D, E	3670 N	-	-
NUTM12Txx	A	5670 N	5050 N	4440 N
	D, E	4250 N	-	-
NUTM16xx	A	5670 N	4660 N	4440 N
	D, E	4250 N	-	-

DIAGRAMS

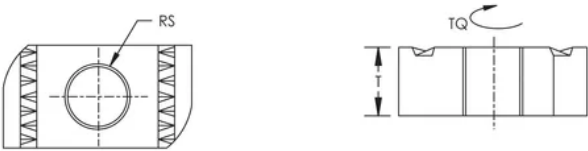

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

欧洲

Netherlands:

+31 800-0200135

France:

+33 800 901 793

欧洲

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
[nVent.com](https://www.nVent.com) CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.