

BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO WOOD/CONCRETE



CERTIFICATIONS



功能

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

技术参数

表面处理: Electrogalvanized

材料: Steel

Table 1/2

物料号	订货号	长度 (L)	棒尺寸 (RS)	螺钉直径 (Sc)	高度 (H)	螺钉长度 (L)
CSBBRS2EG		40.4mm	0.375, 0.5	0.25in	28.2mm	44.5mm
CSBBRS2MEG	402240	40.4mm	10, 12	0.25in	28.2mm	44.5mm


Table 2/2

物料号	订货号	宽度 (W)	钻头直径
CSBBRS2EG		26.9mm	5mm
CSBBRS2MEG	402240	26.9mm	5mm

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

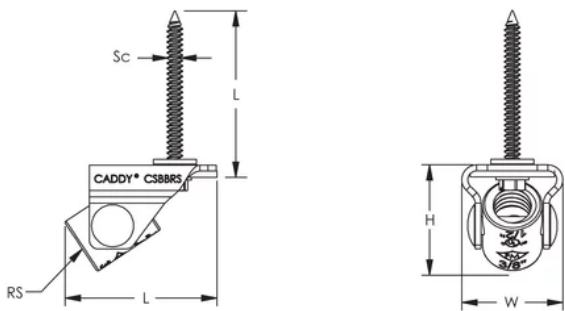

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER