


DISCONNECTING LINK

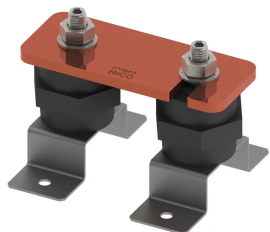

功能

Allows for quick and easy disconnection of the earthing system to facilitate testing of the earth in isolation

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes halogen-free polyamide insulators, stainless steel (EN 1.4401) hardware and mounting brackets

技术参数

材料: Copper

符合: IEC® EN 62561-1:2017 Class H

Table 1/2

物料号	表面处理	宽度 1 (W1)	宽度 2 (W2)	高度 (H)	厚度 (T)	长度 (L)
DLINKC	Bare	100mm	50mm	90mm	6mm	125mm
DLINKT	Tinned	100mm	50mm	90mm	6mm	125mm


Table 2/2

物料号	螺纹尺寸 (TS)	元件重量
DLINKC	M10	0.77kg
DLINKT	M10	0.77kg

ADDITIONAL PRODUCT DETAILS

Tinned finish is 8 microns according to ASTM B545 Service Class "C" for corrosive environments.

DIAGRAMS

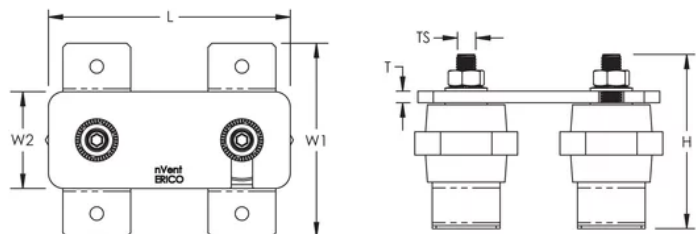

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.