


## ELECTRICAL EARTH BAR, BARE, 22 CONNECTIONS, 0 NUMBER OF DISCONNECTS, 1,250 MM

### 目录编号

**EEB22C506D0A**

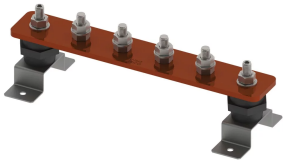

### 功能

Provides a convenient, single-point grounding and bonding location

Busbars with disconnect links allow for convenient testing of the earth termination system

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes halogen-free polyamide insulators, stainless steel (EN 1.4401) hardware and mounting brackets

Custom bars can be designed and manufactured to customer specifications

### 产品属性

符合: IEC® EN 62561-1:2017 Class H

材料: Copper

表面处理: Bare

连接件数量: 22

断开数量: 0

螺纹尺寸 (TS): M10

高度 (H): 94mm

长度 (L): 1250mm

宽度 1 (W1): 100mm

宽度 2 (W2): 50mm

厚度 (T): 6mm

 
A: 50mm

元件重量: 5.33kg

ADDITIONAL PRODUCT DETAILS

Tinned finish is 8 microns according to ASTM B545 Service Class "C" for corrosive environments.

DIAGRAMS



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:  
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER