


FOUR POLE DISTRIB. BLOCK WITH THREADED BARS, FLAT, 630 A

目录编号

TRC-630A

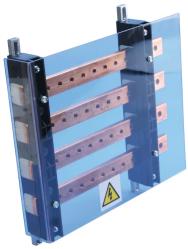

CERTIFICATIONS



功能

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

产品属性

Article Number: 563190

材料: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

最大工作电压, IEC(Ui): 1000

Peak Short Circuit Current (Ipk): 84kA

短期耐受电流(Icw) 1s: 52kA

线路端连接数量: 1

负载端连接数量: 8

孔尺寸 (HS): 10mm

螺纹尺寸 (TS): M8

深度 (D): 60mm

高度 (H): 338 – 390mm

宽度 (W): 340mm

A: 290mm

元件重量: 4.8kg


阻燃: UL® 94V-0

符合: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

DIAGRAMS

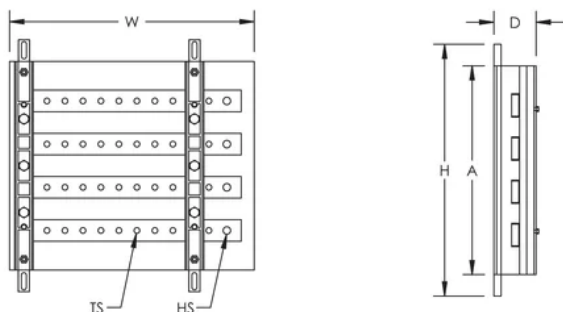

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:
[nVent.com](https://www.nVent.com) CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.