


NVENT ERIFLEX FLEXBUS HCBC CLAMP

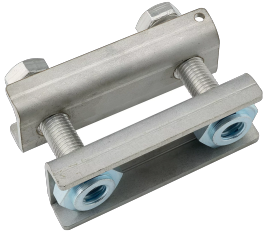

CERTIFICATIONS



功能

Rigid design assures even contact pressure

Installs quickly and easily

Ideal for on-site modifications

Made with non-magnetic material stainless steel for high-current connections to prevent the formation of magnetic fields

Contains crimped self-locking nut for vibration resistance and easy installation

No drilling needed to fix the Flexbus Conductor on the transformer/power supply palm

Includes voltage detection connecting point

RoHS compliant

技术参数

材料: Stainless Steel 304 (EN 1.4301)

Table 1/2

物料号	订货号	厚度 (T)	电缆厚度	扭矩 (TQ)	孔尺寸 (HS)	A
FLEXCLAMP100	508192	4mm	90 – 100mm	100N • m	5.5mm	100mm
FLEXCLAMP120	508193	4mm	110 – 120mm	100N • m	5.5mm	120mm
FLEXCLAMP160	508194	4mm	130 – 160mm	100N • m	5.5mm	160mm
FLEXCLAMP63	508190	4mm	30 – 63mm	100N • m	5.5mm	63mm
FLEXCLAMP80	508191	4mm	70 – 80mm	100N • m	5.5mm	80mm

Table 2/2

物料号	订货号	B	元件重量	C	D
FLEXCLAMP100	508192	160mm	0.92kg	20mm	43mm
FLEXCLAMP120	508193	180mm	1kg	20mm	43mm
FLEXCLAMP160	508194	220mm	1.32kg	20mm	43mm
FLEXCLAMP63	508190	123mm	0.53kg	20mm	43mm
FLEXCLAMP80	508191	140mm	0.84kg	20mm	43mm


ADDITIONAL PRODUCT DETAILS

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

The minimum clearance distance is 14mm according to IEC 61439-1 with air pollution degree 3. If this distance cannot be respected, insulation material should be added between the metallic LV cover and the HCBC clamp. Flexbus IP2x Boots is also a solution.

If the Flexbus Conductors have a horizontal entry, an extender needs to be added between the power supply palm and HCBC Clamp and Plate.

DIAGRAMS

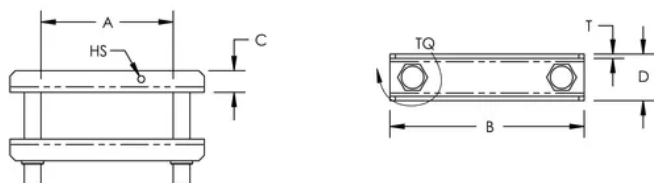

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.