


TELECOM GROUNDING BUSBAR

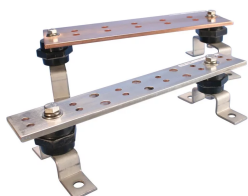

CERTIFICATIONS



功能

Meets TIA-607-C and TIA-607-D conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

技术参数

厚度 (T): 6.35mm

宽度 (W): 50.8mm

材料: Copper


Table 1/2

物料号	长度 1 (L1)	长度 2 (L2)	镀锡	孔洞尺寸 1(成对数)	孔洞尺寸 2(成对数)	C
TGBA12L06P	305mm	229mm	No	6	3	15.9mm

物料号	长度 1 (L1)	长度 2 (L2)	镀锡	孔洞尺寸 1(成对数)	孔洞尺寸 2(成对数)	C
TGBA12L06PT	305mm	229mm	Yes	6	3	15.9mm
TGBA16L08P	394mm	229mm	No	8	3	15.9mm
TGBA16L08PT	394mm	229mm	Yes	8	3	15.9mm
TGBA18L10P	451mm	229mm	No	10	3	15.9mm
TGBA18L10PT	451mm	229mm	Yes	10	3	15.9mm
TGBA20L12P	508mm	229mm	No	12	3	15.9mm
TGBA20L12PT	508mm	229mm	Yes	12	3	15.9mm
TGBA24L14P	610mm	457mm	No	14	5	15.9mm
TGBA24L14PT	610mm	457mm	Yes	14	5	15.9mm
TGBA29L18P	737mm	457mm	No	18	5	15.9mm
TGBA29L18PT	737mm	457mm	Yes	18	5	15.9mm

Table 2/2				
物料号	B	A	孔洞尺寸 1 (HS1)	孔洞尺寸 2 (HS2)
TGBA12L06P	28.6mm	25.4mm	8mm	11mm
TGBA12L06PT	28.6mm	25.4mm	8mm	11mm
TGBA16L08P	28.6mm	25.4mm	8mm	11mm
TGBA16L08PT	28.6mm	25.4mm	8mm	11mm
TGBA18L10P	28.6mm	25.4mm	8mm	11mm
TGBA18L10PT	28.6mm	25.4mm	8mm	11mm
TGBA20L12P	28.6mm	25.4mm	8mm	11mm
TGBA20L12PT	28.6mm	25.4mm	8mm	11mm
TGBA24L14P	28.6mm	25.4mm	8mm	11mm
TGBA24L14PT	28.6mm	25.4mm	8mm	11mm
TGBA29L18P	28.6mm	25.4mm	8mm	11mm
TGBA29L18PT	28.6mm	25.4mm	8mm	11mm

 DIAGRAMS



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER