


带直通信号线的背板

带直通信号线的背板。

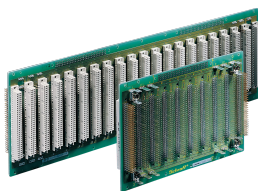

CERTIFICATIONS



功能

电源在每个连接器的第 1 排 + 32

2 层背板, 含电源连接的适配区域

技术参数

Table 1/2						
物料号	产品类型	Number of Slots	机架高度	Backplane Type	Slot Width	Connector Type
23007-010	背板	10	3U	60 信号线	4HP	C64F
23007-021	背板	21	3U	60 信号线	4HP	C64F
23007-040	背板	10	3U	60 信号线	4HP	C96F
23007-051	背板	21	3U	60 信号线	4HP	C96F
23007-081	背板	21	3U	60 信号线	4HP	
23007-114	背板	14	3U	60 信号线	3HP	C64F

物料号	产品类型	Number of Slots	机架高度	Backplane Type	Slot Width	Connector Type
23007-128	背板	28	3U	60 信号线	3HP	C64F
23007-158	背板	28	3U	60 信号线	3HP	C96F
23007-188	背板	28	3U	60 信号线	3HP	
23007-410	背板	10	3U	90 信号线	4HP	C96F
23007-421	背板	21	3U	90 信号线	4HP	C96F

Table 2/2		
物料号	Power Connector Type	包装数量
23007-010	Fastons 6.3 x 0.8 mm	1
23007-021	Fastons 6.3 x 0.8 mm	1
23007-040	Fastons 6.3 x 0.8 mm	1
23007-051	Fastons 6.3 x 0.8 mm	1
23007-081	Fastons 6.3 x 0.8 mm	1
23007-114	Fastons 6.3 x 0.8 mm	1
23007-128	Fastons 6.3 x 0.8 mm	1
23007-158	Fastons 6.3 x 0.8 mm	1
23007-188	Fastons 6.3 x 0.8 mm	1
23007-410	Fastons 6.3 x 0.8 mm	1
23007-421	Fastons 6.3 x 0.8 mm	1

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.