


前把手 单件包装, 宽度 12.2 MM

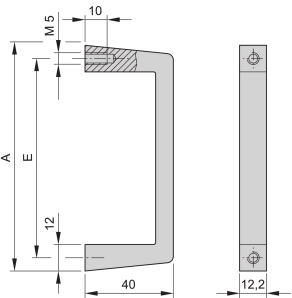

把手可以装配到插箱或 19" 面板上。可提供无色或黑色阳极氧化表面。把手将从后侧用螺栓固定。

CERTIFICATIONS



功能

静态承载能力 30 千克/对

从后面螺栓固定

技术参数

Table 1/2						
物料号	产品类型	适用于	Handle Type	机架高度	材料	颜色
10501-116	把手	插箱	平角	1U	铝	银色
10501-004	把手	插箱	平角	2U	铝	银色
10501-005	把手	插箱	平角	3U	铝	银色
10501-006	把手	插箱	平角	4U	铝	银色
10501-007	把手	插箱	平角	5U	铝	银色
10501-008	把手	插箱	平角	6U	铝	银色
10501-016	把手	插箱	平角	2U	铝	银色

物料号	产品类型	适用于	Handle Type	机架高度	材料	颜色
10501-018	把手	插箱	平角	4U	铝	银色
10501-020	把手	插箱	斜把手	3U	铝	银色
10501-021	把手	插箱	斜把手	4U	铝	银色
10501-022	把手	插箱	斜把手	6U	铝	银色
10501-025	把手	插箱	平角	2U	铝	黑色
10501-026	把手	插箱	平角	3U	铝	黑色
10501-027	把手	插箱	平角	4U	铝	黑色
10501-028	把手	插箱	平角	5U	铝	黑色
10501-029	把手	插箱	平角	6U	铝	黑色

Table 2/2			
物料号	包装数量	表面处理	Torque
10501-116	1	阳极氧化	
10501-004	1	阳极氧化	
10501-005	1	阳极氧化	2.4N • m
10501-006	1	阳极氧化	
10501-007	1	阳极氧化	
10501-008	1	阳极氧化	2.4N • m
10501-016	1	阳极氧化	
10501-018	1	阳极氧化	2.4N • m
10501-020	1	阳极氧化	2.4N • m
10501-021	1	阳极氧化	2.4N • m
10501-022	1	阳极氧化	2.4N • m
10501-025	1	阳极氧化	
10501-026	1	阳极氧化	2.4N • m
10501-027	1	阳极氧化	
10501-028	1	阳极氧化	
10501-029	1	阳极氧化	2.4N • m

ADDITIONAL PRODUCT DETAILS

请单独订购装配套件。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER