


INTERMEDIATE ADAPTER TO ASSEMBLE SEVERAL 3 U TESTADAPTER

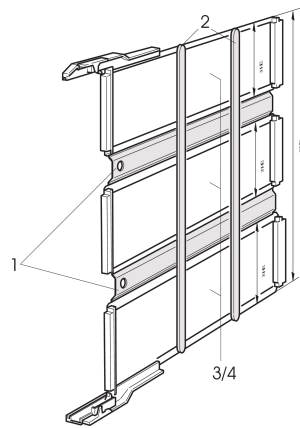

支架套件，可基于 3 U 测试转接卡制作 6/9 U 测试转接卡。适合带 DIN 41612 连接器的 B、C、E 和 F 型测试转接卡。

CERTIFICATIONS



功能

适用 B, C, D, E, F

技术参数

Table 1/1				
物料号	适用于	材料	包装数量	表面处理
20800-168	测试转接卡	碳钢	2	粉末涂层
20800-224	测试转接卡	碳钢	2	粉末涂层
20800-278	测试转接卡	碳钢	2	粉末涂层
20800-279	测试转接卡	碳钢	2	粉末涂层
23040-001	测试转接卡	碳钢	2	粉末涂层

ADDITIONAL PRODUCT DETAILS

适合 D 型 DIN 连接器的测试转接卡无法与其他类型转接卡卡结合使用。

VMEbus 测试转接卡深度（尺寸 B）位于相应产品页面。

B、C、D、E、F 型测试转接卡深度（尺寸 B）位于相应产品页面

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER