



NVENT CADDY MACROFIX 绝缘 M8/M10



CERTIFICATIONS



功能

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory☒

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

颜色: 黑色

表面处理: 电镀锌

材料: Steel;EPDM-SBR Rubber

温度: -50 至 110 °C

Table 1/2

物料号	商品号	外径 (OD)	管道尺寸	NB/DN	棒尺寸 (RS)	宽度 (W)
MFD015	586001	11 - 15 mm	1/4"	8	8, 10	20 mm
MFD019	586002	15 - 19 mm	3/8"	10	8, 10	20 mm
MFD025	586003	19 - 25 mm	1/2"	15	8, 10	20 mm
MFD031	586004	25 - 31 mm	3/4"	20	8, 10	20 mm
MFD037	586005	31 - 37 mm	1"	25	8, 10	20 mm
MFD044	586006	37 - 44 mm	1 1/4"	32	8, 10	20 mm
MFD050	586007	44 - 50 mm	1 1/2"	40	8, 10	20 mm
MFD058	586008	50 - 58 mm			8, 10	20 mm
MFD068	586009	58 - 68 mm	2"	50	8, 10	20 mm
MFD078	586010	68 - 78 mm	2 1/2"	65	8, 10	23 mm
MFD088	586011	78 - 88 mm			8, 10	23 mm
MFD098	586012	88 - 98 mm	3"	80	8, 10	23 mm
MFD108	586013	98 - 108 mm	3 1/2"	90	8, 10	23 mm
MFD118	586014	108 - 118 mm	4"	100	8, 10	23 mm
MFD128	586015	118 - 128 mm			8, 10	23 mm
MFD138	586016	128 - 138 mm			8, 10	23 mm
MFD148	586017	138 - 148 mm	5"	125	8, 10	25 mm
MFD160	586018	150 - 160 mm			8, 10	25 mm
MFD170	586019	160 - 170 mm	6"	150	8, 10	25 mm
MFD200	586020	190 - 200 mm			8, 10	27 mm
MFD215	586021	205 - 215 mm			8, 10	27 mm
MFD225	586022	215 - 225 mm	8"	200	8, 10	27 mm
MFD250	586023	239 - 250 mm			8, 10	30 mm
MFD275	586024	265 - 275 mm	10"	250	8, 10	30 mm
MFD319	586025	309 - 319 mm			8, 10	30 mm


Table 2/2

物料号	商品号	厚度 (T)	螺钉直径 (Sc)	螺钉长度 (L)	静态负载 (F)
MFD015	586001	1 mm	6	17mm	1000N
MFD019	586002	1 mm	6	17mm	1000N
MFD025	586003	1 mm	6	22mm	1000N
MFD031	586004	1 mm	6	22mm	1000N
MFD037	586005	1 mm	6	22mm	1000N
MFD044	586006	1 mm	6	27mm	1000N
MFD050	586007	1.25 mm	6	27mm	1500N
MFD058	586008	1.25 mm	6	27mm	1500N
MFD068	586009	1.25 mm	6	32mm	1500N
MFD078	586010	1.5 mm	6	32mm	2000N
MFD088	586011	1.5 mm	6	32mm	2000N
MFD098	586012	1.75 mm	6	37mm	2500N
MFD108	586013	1.75 mm	6	37mm	2500N
MFD118	586014	1.75 mm	6	37mm	2500N
MFD128	586015	2 mm	6	37mm	3000N
MFD138	586016	2 mm	6	37mm	3000N
MFD148	586017	2 mm	6	37mm	3200N
MFD160	586018	2 mm	6	37mm	3200N
MFD170	586019	2 mm	6	37mm	3200N
MFD200	586020	2.25 mm	6	37mm	3600N
MFD215	586021	2.25 mm	6	37mm	3600N
MFD225	586022	2.25 mm	6	37mm	3600N
MFD250	586023	2.5 mm	6	37mm	4000N
MFD275	586024	2.5 mm	6	37mm	4000N
MFD319	586025	2.5 mm	6	37mm	4000N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

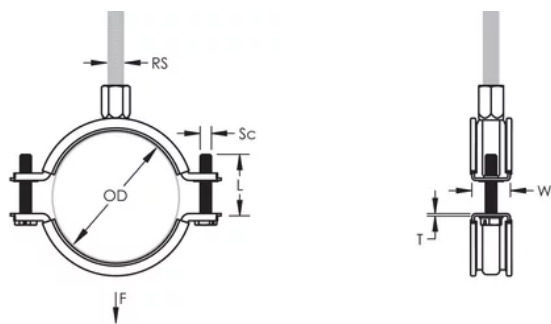

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美
+1.800.753.9221
Option 1 - Customer Care
Option 2 - Technical
Support

欧洲
Netherlands:
+31 800-0200135
France:
+33 800 901 793

欧洲
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER