



NVENT CADDY PYRAMID ST 固定支柱支撑件



CERTIFICATIONS



功能

- Provides superior support for pipe, conduit, cable tray and equipment
- 底部采用泡沫材料，可以减少界面磨损，更好地保护屋顶膜材
- Compatible with roof surfaces including single ply, bituminous, metal and spray foam
- Provides superior load distribution, even with varying rooftop surfaces
- 开箱即用，节约安装时间和人力
- Multiple sizes and load ratings offer the ability to tailor the solution to the application
- Easy to transport to the roof
- Hot-dip galvanized and UV stabilized for long lasting performance

SPECIFICATIONS

Static Load Safety Factor:	3:1
表面处理:	热浸镀锌
材料:	Polyethylene;Polypropylene;Steel

温度: -45 至 65 °C

Table 1/2

物料号	商品号	长度 1 (L1)	Length 2 (L2)	高度 (H)	宽度 (W)	Surface Area
PSF6C	360463	152 mm	203 mm	122 mm	152 mm	26452mm ²
PSF10C	360464	254 mm	317.5 mm	122 mm	203 mm	59355mm ²
PSF16C	360466	406 mm	483 mm	122 mm	203 mm	91613mm ²


Table 2/2

物料号	商品号	单位重量	静态负载 (F)	认证
PSF6C	360463	0.5 kg	1334N	
PSF10C	360464	1 kg	4450N	ITB
PSF16C	360466	1.5 kg	6670N	ITB

ADDITIONAL PRODUCT DETAILS

Static load at 73.1 kPa (10.6 psi) roof loading. Contact project or roofing engineer for maximum allowable load on individual project roof system.

DIAGRAMS

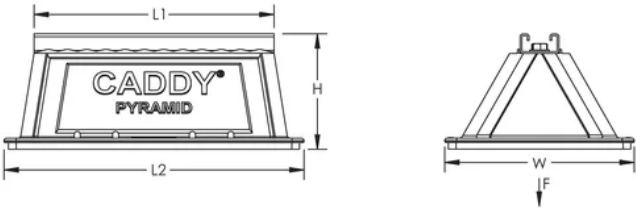

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

欧洲

Netherlands:

+31 800-0200135

France:

+33 800 901 793

欧洲

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
[nVent.com](https://www.nVent.com) CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.