



NVENT CADDY PYRAMID 通用支撑件



功能

- Captive stainless steel nuts allow for custom attachment methods to the support base including easy attachment of stainless steel strut, threaded rod or other project-specific hardware
- 底部采用泡沫材料，可以减少界面磨损，更好地保护屋顶膜材
- Compatible with roof surfaces including single ply, bituminous, metal and spray foam
- Provides superior load distribution, even with varying rooftop surfaces
- Multiple sizes and load ratings offer the ability to tailor the solution to the application
- Includes square holes for creating an H-Frame with a 12" (305 mm) cross support (PBU16 only)
- Base is manufactured from UV-stabilized thermoplastic material

SPECIFICATIONS


Static Load Safety Factor:	3:1
材料:	Polyethylene;Polypropylene;Stainless Steel 18-8 (EN 1.4305)
温度:	-45 至 65 °C

Table 1/2						
物料号	商品号	长度 1 (L1)	Length 2 (L2)	高度 (H)	宽度 (W)	螺纹尺寸 (TS)
PBU6M	360495	140 mm	196 mm	102 mm	150 mm	M10
PBU10M	360496	254 mm	318 mm	102 mm	201 mm	M10
PBU16M	360497	406 mm	480 mm	102 mm	201 mm	M10

Table 2/2

物料号	商品号	Hole Quantity	A	B	Surface Area	静态负载 (F)
PBU6M	360495	3	114 mm	57 mm	26452mm ²	1330N
PBU10M	360496	2	218 mm		59355mm ²	4450N
PBU16M	360497	2	165 mm		91613mm ²	6670N

DIAGRAMS

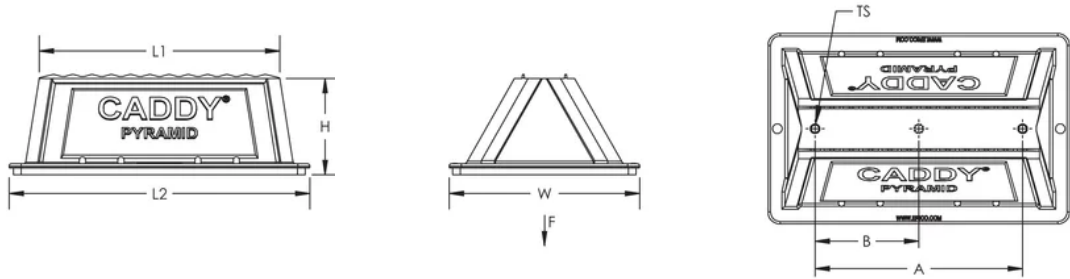

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

欧洲

Netherlands: +31 800-0200135

France: +33 800 901 793

欧洲

Germany: 800 1890272

Other Countries: +31 13 5835404

APAC

Shanghai: + 86 21 2412 1618/19

Sydney: +61 2 9751 8500