



NVENT CADDY SPEED LINK SLK WITH THREADED STUD END



CERTIFICATIONS



功能

- Complete system includes wire, locking device and pre-assembled threaded stud end fitting
- Attaches to structures with threaded anchors or devices with threaded hole
- Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

SPECIFICATIONS


- Static Load Safety Factor: 5:1
- 表面处理: 电镀锌
- 材料: Steel;Polypropylene;Zinc Alloy
- 符合: SMACNA HVAC-DCS

Table 1/2						
物料号	商品号	Wire Rope Diameter	Wire Rope Length	棒尺寸 (RS)	螺钉长度 (L)	高度 (H)
SLK2L3SEM8	196561	2 mm	3m	8	45mm	55 mm

物料号	商品号	Wire Rope Diameter	Wire Rope Length	棒尺寸 (RS)	螺钉长度 (L)	高度 (H)
SLK2L5SEM8	196563	2 mm	5m	8	45mm	55 mm
SLK3L2SEM10	196718	3 mm	2m	10	45mm	62 mm
SLK3L3SEM10	196719	3 mm	3m	10	45mm	62 mm
SLK3L5SEM10	196720	3 mm	5m	10	45mm	62 mm

Table 2/2						
物料号	商品号	宽度 (W)	厚度 (T)	角 (a)	静态负载 (F)	认证
SLK2L3SEM8	196561	19 mm	12.5 mm	90 ° Max	440N	cUL, UL
SLK2L5SEM8	196563	19 mm	12.5 mm	90 ° Max	440N	cUL, UL
SLK3L2SEM10	196718	24 mm	16 mm	90 ° Max	890N	
SLK3L3SEM10	196719	24 mm	16 mm	90 ° Max	890N	
SLK3L5SEM10	196720	24 mm	16 mm	90 ° Max	890N	

DIAGRAMS

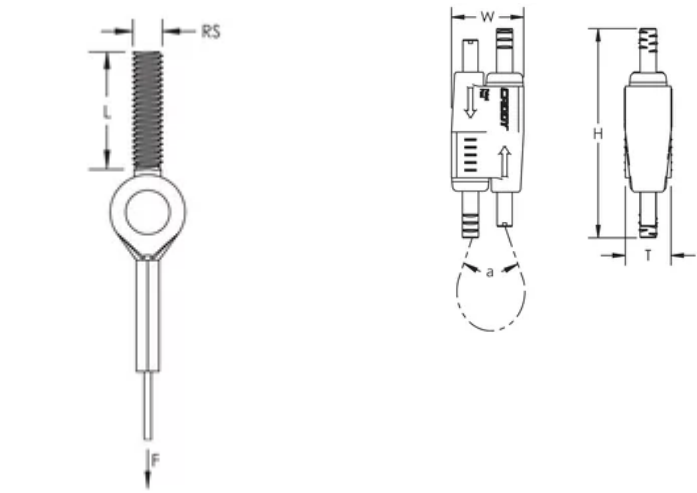

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

欧洲

Netherlands:

+31 800-0200135

France:

+33 800 901 793

欧洲

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.