

BRANCH LINE RESTRAINT PIPE ATTACHMENT



CERTIFICATIONS



功能

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

技术参数

表面处理: Electrogalvanized

材料: Steel


Table 1/2

物料号	订货号	NB/DN	管道尺寸	外径 (OD)	长度 (L)	棒尺寸 (RS)
-----	-----	-------	------	---------	--------	----------

CSBBRP0100EG	404477	25	1in	33.4mm	41.4mm	10, 12
CSBBRP0125EG	404478	32	1.25in	42.2mm	50mm	10, 12
CSBBRP0150EG	404479	40	1.5in	48.3mm	56.1mm	10, 12
CSBBRP0200EG	404480	50	2in	60.3mm	68.3mm	10, 12

Table 2/2			
物料号	订货号	高度 (H)	宽度 (W)
CSBBRP0100EG	404477	73.7mm	22.2mm
CSBBRP0125EG	404478	82.6mm	22.2mm
CSBBRP0150EG	404479	88.9mm	22.2mm
CSBBRP0200EG	404480	100.3mm	22.2mm

DIAGRAMS

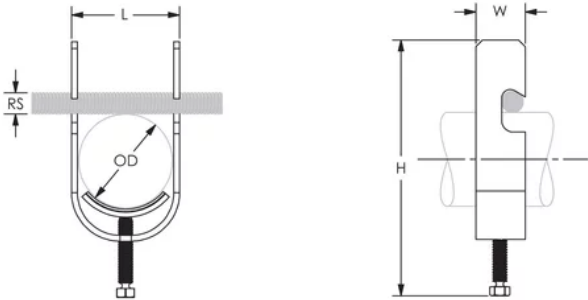

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:
[nVent.com](https://www.nVent.com) CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.