


## TELECOM GROUNDING BUSBAR

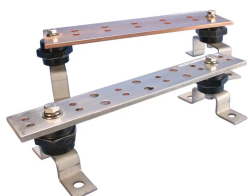

### CERTIFICATIONS



### 功能

Meets TIA-607-C and TIA-607-D conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

### 技术参数

厚度 (T): 6.35mm

宽度 (W): 50.8mm

材料: Copper


Table 1/2

| 物料号        | 长度 1 (L1) | 长度 2 (L2) | 镀锡 | 孔洞尺寸<br>1(成对数) | 孔洞尺寸<br>2(成对数) | C      |
|------------|-----------|-----------|----|----------------|----------------|--------|
| TGBA12L06P | 305mm     | 229mm     | No | 6              | 3              | 15.9mm |

| 物料号         | 长度 1 (L1) | 长度 2 (L2) | 镀锡  | 孔洞尺寸<br>1(成对数) | 孔洞尺寸<br>2(成对数) | C      |
|-------------|-----------|-----------|-----|----------------|----------------|--------|
| TGBA12L06PT | 305mm     | 229mm     | Yes | 6              | 3              | 15.9mm |
| TGBA16L08P  | 394mm     | 229mm     | No  | 8              | 3              | 15.9mm |
| TGBA16L08PT | 394mm     | 229mm     | Yes | 8              | 3              | 15.9mm |
| TGBA18L10P  | 451mm     | 229mm     | No  | 10             | 3              | 15.9mm |
| TGBA18L10PT | 451mm     | 229mm     | Yes | 10             | 3              | 15.9mm |
| TGBA20L12P  | 508mm     | 229mm     | No  | 12             | 3              | 15.9mm |
| TGBA20L12PT | 508mm     | 229mm     | Yes | 12             | 3              | 15.9mm |
| TGBA24L14P  | 610mm     | 457mm     | No  | 14             | 5              | 15.9mm |
| TGBA24L14PT | 610mm     | 457mm     | Yes | 14             | 5              | 15.9mm |
| TGBA29L18P  | 737mm     | 457mm     | No  | 18             | 5              | 15.9mm |
| TGBA29L18PT | 737mm     | 457mm     | Yes | 18             | 5              | 15.9mm |

| Table 2/2   |        |        |              |              |
|-------------|--------|--------|--------------|--------------|
| 物料号         | B      | A      | 孔洞尺寸 1 (HS1) | 孔洞尺寸 2 (HS2) |
| TGBA12L06P  | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA12L06PT | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA16L08P  | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA16L08PT | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA18L10P  | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA18L10PT | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA20L12P  | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA20L12PT | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA24L14P  | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA24L14PT | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA29L18P  | 28.6mm | 25.4mm | 8mm          | 11mm         |
| TGBA29L18PT | 28.6mm | 25.4mm | 8mm          | 11mm         |

 DIAGRAMS



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).



Our powerful portfolio of brands:  
[nVent.com](http://nVent.com) CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER