


FRONT/REAR TOP FRAMES FOR FLOOR STANDING ENCLOSURES, MCU

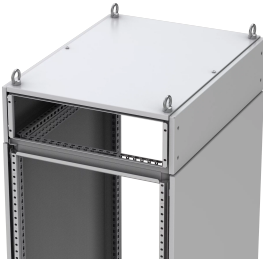

This frame creates additional space in the top and can be segregated from the enclosure. It has a universal hole pattern for mounting accessories easily.

功能

Description: For covering the sides of the top cabling frame MCU. Mounted with 4 screws and new patented retainers.

Side panels: MCUP supplied as an accessory.

Material: 1.35 mm steel plate.

Finish: RAL 7035 structured powder coating.

Protection: IP55-compliant.

Pack quantity: 2 panels with mounting accessories.

技术参数

颜色: RAL7035

表面处理: Plated

颜色代码: RAL 7035

材料: 钢

Table 1/1						
物料号	订货号	高度	宽度	深度	外壳材质	快速发货
MCU2046R5		200mm	400mm	600mm	钢	No
MCU2048R5	MCU2048R5	200mm	400mm	800mm	钢	No
MCU2065R5		200mm	599mm	500mm	钢	No
MCU2066R5		200mm	599mm	600mm	钢	No
MCU2068R5	MCU2068R5	200mm	600mm	800mm	钢	No
MCU2085R5		200mm	800mm	500mm	钢	No
MCU2086R5		200mm	800mm	600mm	钢	No
MCU2088R5	MCU2088R5	200mm	800mm	800mm	钢	No
MCU2105R5		200mm	999mm	500mm	钢	No
MCU2106R5		200mm	999mm	600mm	钢	No
MCU2108R5	MCU2108R5	200mm	1000mm	800mm	钢	No
MCU2125R5		200mm	1199mm	500mm	钢	No
MCU2126R5		200mm	1199mm	600mm	钢	No
MCU2128R5	MCU2128R5	200mm	1200mm	800mm	钢	No
MCU3048R5	MCU3048R5	300mm	400mm	800mm	钢	No
MCU3066R5		300mm	599mm	600mm	钢	No
MCU3068R5	MCU3068R5	300mm	600mm	800mm	钢	No
MCU3086R5		300mm	800mm	600mm	钢	No
MCU3088R5	MCU3088R5	300mm	800mm	800mm	钢	No
MCU3106R5		300mm	999mm	600mm	钢	No
MCU3108R5	MCU3108R5	300mm	999mm	800mm	钢	No
MCU3126R5		300mm	1199mm	600mm	钢	No
MCU3128R5	MCU3128R5	300mm	1199mm	800mm	钢	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.