


半高摇架，SFCP

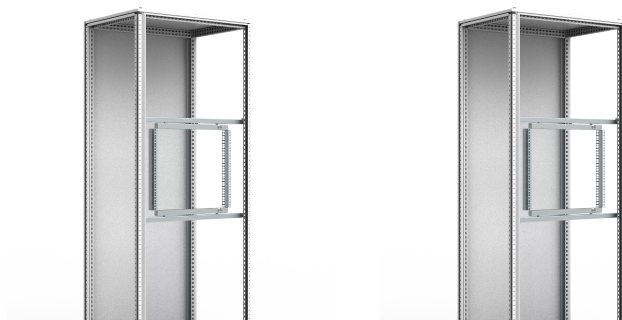

A partial height swing frame for 19" equipment that provides additional mounting space for such equipment, as well as rear access to the fitted components and equipment once opened.

功能

Description: Partial height swing frame for 19" -components allowing left or right hand opening. Can be used in wall mounted, steel enclosures, and floor standing, combinable and compact, steel enclosures. Rigid S-shaped frame profile equipped with 19" hole pattern in front and back. Zinc plated frame for direct earthing of the mounted components. Standard opening angle 125°-155°. Mounting in wall mounted, steel enclosures requires the SFBP transversal support in combination with the AVB. Mounting in floor standing steel combinable enclosures requires the SFBP transversal support.

Lock: 1 double-bit 3 mm lock.

Material: 2 mm zinc plated steel.

Pack quantity: 1 swing frame with hinges.

Mounting requirements: Mounting in wall mounted, steel enclosures requires the SFBP transversal support in combination with the AVB. Mounting in floor standing steel combinable enclosures requires the SFBP transversal support. Adjustable in depth in combination with CLPK profiles.

技术参数

厚度: 2mm

材料: 碳钢

表面处理: 镀锌

Table 1/1						
物料号	订货号	高度	宽度	深度	外壳材质	产品系列
SFCP036	SFCP036	600mm	496mm	60mm	碳钢	
SFCP066	SFCP066	600mm	496mm	60mm	碳钢	Free-Standing, Wall Mounted
SFCP106	SFCP106	600mm	496mm	60mm	碳钢	
SFCP126	SFCP126	800mm	696mm	60mm	碳钢	
SFCP156	SFCP156	800mm	696mm	60mm	碳钢	
SFCP196	SFCP196	1000mm	896mm	60mm	碳钢	
SFCP246	SFCP246	1200mm	1096mm	60mm	碳钢	

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。